










THE FOLLOWING DIAGRAMS ILLUSTRATE SOME COMMON BATTERY PACK CONFIGURATIONS. PLEASE USE THIS AS A GUIDE WHEN ORDERING CUSTOM PACKS.

~ ~







NOTE IN SOME INSTANCES, A PACK WILL CONTAIN CURRENT AND TEMPERATURE SENSING AND PROTECTION DEVICES. PLEASE CHECK PACK CAREFULLY FOR THESE BEFORE ORDERING.


CUSTOM PACK ASSEMBLIES

SINGLE CELL (Side by Side)

		
Style 1 2.4 Volts 2 Cells	Style 2 3.6 Volts 3 Cells	Style 3 4.8 Volts 4 Cells
		
Style 4 6.0 Volts 5 Cells	Style 5 7.2 Volts 6 Cells	Style 6 8.4 Volts 7 Cells
		
Style 7 9.6 Volts 8 Cells	Style 8 10.8 Volts 9 Cells	Style 9 12 Volts 10 Cells

SINGLE CELL (Stacked)

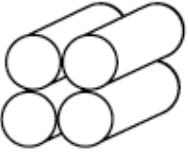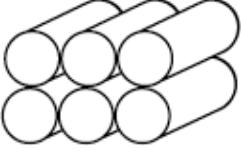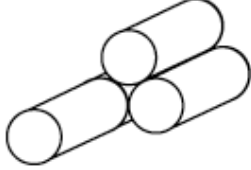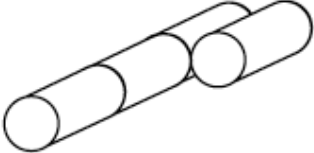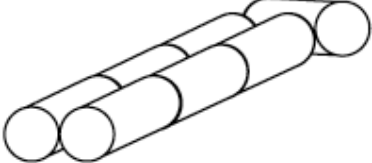
		
Style 10 4.8 Volts 4 Cells	Style 11 7.2 Volts 6 Cells	Style 30 4.8 Volts 4 Cells
		
Style 31 4.8 Volts 4 Cells	Style 32 8.4 Volts 7 Cells	Style 33 8.4 Volts 7 Cells

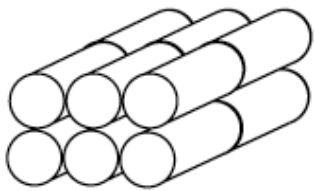

Style 34

14.4 Volts


12 Cells

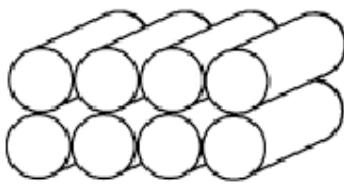

Style 12

9.6 Volts

8 Cells

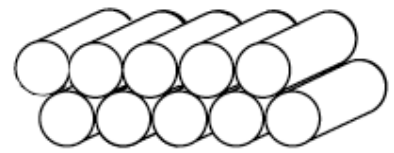


Style 13

12.0 Volts

10 Cells

 SINGLE CELL (End to End)



Style 14

2.4 Volts


2 Cells



Style 15

3.6 Volts

 
3 Cells



Style 16

4.8 Volts

 
4 Cells



Style 17

6.0 Volts


5 Cells

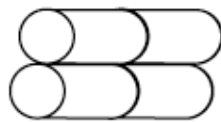

Style 18

4.8 Volts


4 Cells

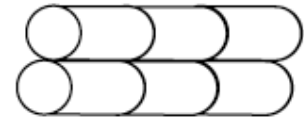

Style 19

7.2 Volts


6 Cells

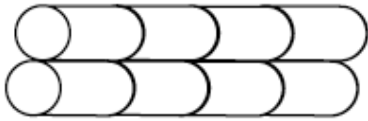

Style 20

9.6 Volts


8 Cells

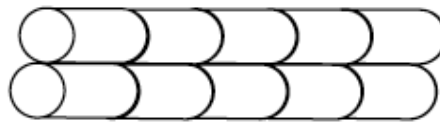

Style 21

12.0 Volts


10 Cells

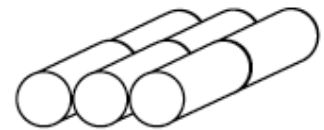

Style 22

7.2 Volts

6 Cells

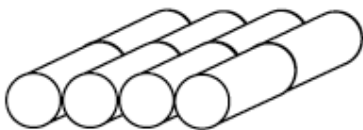

Style 23

9.6 Volts


8 Cells



Style 24

12.0 Volts

10 Cells


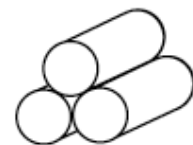







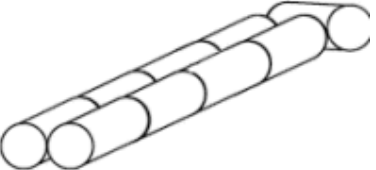
Style 25

3.6 Volts

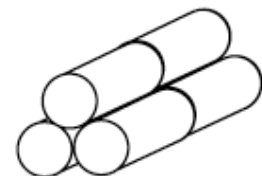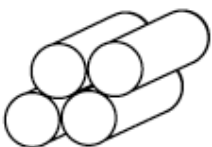3 Cells

SINGLE CELL (Stacked)



Style 26	4.8 Volts	4 Cells	Style 27	6.0 Volts	5 Cells	Style 29	7.6 Volts	6 cells
								
Style 28	9.6 Volts	8 Cells	Style 35	9.6 Volts	8 Cells	Style 36	10.8 Volts	9 Cells
								
Style 37	12.0 Volts	10 Cells	Style 38	13.2 Volts	11 Cells	Style 39	10.8 Volts	9 Cells